


VITE A TESTA CILINDRICA CON ESAGONO INCASSATO
CYLINDRICAL HEAD SCREW WITH HEXAGON SOCKET
 ZYLINDERKOPFSCHRAUBE MIT INNENSECHSKANT

EV-1

UNI 5931
DIN 912

Classe di resistenza: 12,9
Property class: 12,9
Widerstandsfähigkeit: 12,9

Specifiche: Filettatura ISO Passo Grosso, DIN 13-1
Specification: Threading ISO Coarse Metric DIN 13-1
Spezifikationen: Gewinde ISO Metrisches DIN 13-1

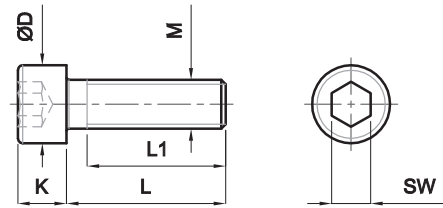

| M | D | K | SW | L1 | L | M | D | K | SW | L1 | L | M | D | K | SW | L1 | L | M | D | K | SW | L1 | L | M | D | K | SW | L1 | L |
|---|-----|---|----|------|-----|---|----|---|----|----|-----|----|----|----|----|------|-----|----|----|----|----|----|-----|----|----|----|----|----|-----|
| 4 | 7 | 4 | 3 | 6,4 | 8 | 8 | 13 | 8 | 6 | 9 | 12 | 10 | 16 | 10 | 8 | 12,5 | 16 | 12 | 18 | 12 | 10 | 16 | 20 | 14 | 21 | 14 | 12 | 25 | 30 |
| | | | | 8,4 | 10 | | | | | 11 | 14 | | | | | 14,5 | 18 | | | | | 21 | 25 | | | | | 30 | 35 |
| | | | | 10,4 | 12 | | | | | 13 | 16 | | | | | 16,5 | 20 | | | | | 26 | 30 | | | | | 35 | 40 |
| | | | | 14,4 | 16 | | | | | 15 | 18 | | | | | 21,5 | 25 | | | | | 31 | 35 | | | | | 40 | 45 |
| | | | | 16,4 | 18 | | | | | 17 | 20 | | | | | 26,5 | 30 | | | | | 30 | 40 | | | | | 45 | 50 |
| | | | | 18,4 | 20 | | | | | 22 | 25 | | | | | 31,5 | 35 | | | | | 30 | 45 | | | | | 50 | 55 |
| | | | | 14 | 25 | | | | | 27 | 30 | | | | | 26 | 40 | | | | | 30 | 50 | | | | | 38 | 60 |
| | | | | 14 | 30 | | | | | 22 | 35 | | | | | 26 | 45 | | | | | 30 | 55 | | | | | 38 | 70 |
| | | | | 14 | 35 | | | | | 22 | 40 | | | | | 26 | 50 | | | | | 30 | 60 | | | | | 38 | 80 |
| | | | | 14 | 40 | | | | | 22 | 45 | | | | | 26 | 55 | | | | | 30 | 70 | | | | | 38 | 90 |
| 5 | 8,5 | 5 | 4 | 8 | 10 | | | | | 22 | 50 | | | | | 26 | 60 | | | | | 30 | 80 | | | | | 38 | 100 |
| | | | | 10 | 12 | | | | | 22 | 55 | | | | | 26 | 70 | | | | | 30 | 85 | | | | | 38 | 105 |
| | | | | 14 | 16 | | | | | 22 | 60 | | | | | 26 | 80 | | | | | 30 | 90 | | | | | 38 | 110 |
| | | | | 16 | 18 | | | | | 22 | 70 | | | | | 26 | 85 | | | | | 30 | 100 | | | | | 38 | 120 |
| | | | | 18 | 20 | | | | | 22 | 80 | | | | | 26 | 90 | | | | | 30 | 110 | | | | | 38 | 125 |
| | | | | 23 | 25 | | | | | 22 | 90 | | | | | 26 | 95 | | | | | 30 | 120 | | | | | 44 | 130 |
| | | | | 16 | 30 | | | | | 22 | 100 | | | | | 26 | 100 | | | | | 36 | 125 | | | | | 44 | 140 |
| | | | | 16 | 35 | | | | | 22 | 110 | | | | | 26 | 105 | | | | | 36 | 130 | | | | | 44 | 150 |
| | | | | 16 | 40 | | | | | 22 | 120 | | | | | 26 | 110 | | | | | 36 | 140 | | | | | 44 | 160 |
| 6 | 10 | 6 | 5 | 7,5 | 10 | | | | | 28 | 130 | | | | | 26 | 115 | | | | | 36 | 145 | | | | | 44 | 170 |
| | | | | 9,5 | 12 | | | | | 28 | 140 | | | | | 26 | 120 | | | | | 36 | 150 | | | | | 44 | 180 |
| | | | | 13,5 | 16 | | | | | 28 | 150 | | | | | 32 | 125 | | | | | 36 | 160 | | | | | 44 | 190 |
| | | | | 15,5 | 18 | | | | | 28 | 160 | | | | | 32 | 130 | | | | | 36 | 165 | | | | | 44 | 200 |
| | | | | 17,5 | 20 | | | | | 28 | 180 | | | | | 32 | 135 | | | | | 36 | 170 | | | | | 57 | 210 |
| | | | | 22,5 | 25 | | | | | 28 | 200 | | | | | 32 | 140 | | | | | 36 | 180 | | | | | 57 | 220 |
| | | | | 18 | 30 | | | | | 28 | 220 | | | | | 32 | 145 | | | | | 36 | 190 | | | | | 57 | 240 |
| | | | | 18 | 35 | | | | | | | | | | | 32 | 150 | | | | | 36 | 200 | | | | | 57 | 260 |
| | | | | 18 | 40 | | | | | | | | | | | 32 | 155 | | | | | 49 | 210 | | | | | | |
| | | | | 18 | 45 | | | | | | | | | | | 32 | 160 | | | | | 49 | 220 | | | | | | |
| | | | | 18 | 50 | | | | | | | | | | | 32 | 165 | | | | | 49 | 230 | | | | | | |
| | | | | 18 | 55 | | | | | | | | | | | 32 | 170 | | | | | 49 | 240 | | | | | | |
| | | | | 18 | 60 | | | | | | | | | | | 32 | 175 | | | | | 49 | 250 | | | | | | |
| | | | | 18 | 70 | | | | | | | | | | | 32 | 180 | | | | | 49 | 260 | | | | | | |
| | | | | 18 | 80 | | | | | | | | | | | 32 | 195 | | | | | 49 | 280 | | | | | | |
| | | | | 18 | 90 | | | | | | | | | | | 32 | 200 | | | | | 49 | 300 | | | | | | |
| | | | | 18 | 100 | | | | | | | | | | | | | | | | | | | | | | | | |
| | | | | 18 | 110 | | | | | | | | | | | | | | | | | | | | | | | | |
| | | | | 18 | 120 | | | | | | | | | | | | | | | | | | | | | | | | |

Esempio di ordinativo: MxL **Order example:** MxL **Bestellbeispiel:** MxL

Altre lunghezze disponibili a richiesta - Other lengths supplied on request - Andere Längen auf Anfrage verfügbar



VITE A TESTA CILINDRICA CON ESAGONO INCASSATO

CYLINDRICAL HEAD SCREW WITH HEXAGON SOCKET

ZYLINDERKOPFSCHRAUBE MIT INNENSECHSKANT

EV-1

UNI 5931
DIN 912

| M | D | K | SW | L1 | L | M | D | K | SW | L1 | L | M | D | K | SW | L1 | L | M | D | K | SW | L1 | L |
|----|----|----|----|----|-----|----|----|----|----|----|-----|----|----|----|----|----|-----|---|---|---|----|----|-----|
| 16 | 24 | 16 | 14 | 25 | 30 | | | | | 57 | 230 | | | | | 52 | 200 | | | | | 60 | 180 |
| | | | | 30 | 35 | | | | | 57 | 240 | | | | | 65 | 210 | | | | | 60 | 190 |
| | | | | 35 | 40 | | | | | 57 | 250 | | | | | 65 | 220 | | | | | 60 | 200 |
| | | | | 40 | 45 | | | | | 57 | 260 | | | | | 65 | 230 | | | | | 73 | 220 |
| | | | | 45 | 50 | | | | | 57 | 280 | | | | | 65 | 240 | | | | | 73 | 240 |
| | | | | 50 | 55 | | | | | 57 | 300 | | | | | 65 | 250 | | | | | 73 | 260 |
| | | | | 38 | 60 | 20 | 30 | 20 | 17 | 44 | 50 | | | | | 65 | 260 | | | | | 73 | 280 |
| | | | | 38 | 65 | | | | | 50 | 55 | | | | | 65 | 270 | | | | | 73 | 300 |
| | | | | 38 | 70 | | | | | 54 | 60 | | | | | 65 | 280 | | | | | 73 | 320 |
| | | | | 38 | 80 | | | | | 50 | 65 | | | | | 65 | 290 | | | | | 73 | 340 |
| | | | | 38 | 90 | | | | | 46 | 70 | | | | | 65 | 300 | | | | | 73 | 360 |
| | | | | 38 | 100 | | | | | 46 | 80 | | | | | 65 | 320 | | | | | | |
| | | | | 38 | 110 | | | | | 46 | 85 | 24 | 36 | 24 | 19 | 53 | 60 | | | | | | |
| | | | | 38 | 120 | | | | | 46 | 90 | | | | | 63 | 70 | | | | | | |
| | | | | 44 | 130 | | | | | 46 | 100 | | | | | 54 | 80 | | | | | | |
| | | | | 44 | 140 | | | | | 44 | 110 | | | | | 54 | 90 | | | | | | |
| | | | | 44 | 150 | | | | | 44 | 120 | | | | | 54 | 100 | | | | | | |
| | | | | 44 | 160 | | | | | 52 | 130 | | | | | 54 | 110 | | | | | | |
| | | | | 44 | 170 | | | | | 52 | 140 | | | | | 54 | 120 | | | | | | |
| | | | | 44 | 180 | | | | | 52 | 150 | | | | | 60 | 130 | | | | | | |
| | | | | 44 | 190 | | | | | 52 | 160 | | | | | 60 | 140 | | | | | | |
| | | | | 44 | 200 | | | | | 52 | 170 | | | | | 60 | 150 | | | | | | |
| | | | | 57 | 210 | | | | | 52 | 180 | | | | | 60 | 160 | | | | | | |
| | | | | 57 | 220 | | | | | 52 | 190 | | | | | 60 | 170 | | | | | | |